


# FGSB-MSHS-CB

---

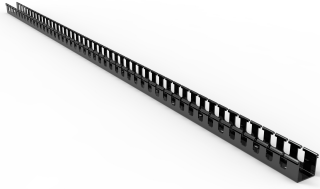

FiberGuide® Vertical Straight Section with 1.5in Slot Spacing, 2x2in, Black

## OBSOLETE

This product was discontinued on: October 1, 2023

### Replaced By:

FGSB-KTW1-JA

FiberGuide® Vertical Duct Kit with 1.5in Slot Spacing and Hinged Cover, 2x2in, Black

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Slotted vertical
<b>Product Brand</b>	FiberGuide®
<b>Product Series</b>	FGS

## General Specifications

<b>Product Feature</b>	Slotted
<b>Color</b>	Black
<b>Orientation</b>	Vertical
<b>Section Type</b>	Straight section

## Dimensions

<b>Height</b>	50.8 mm   2 in
<b>Width</b>	50.8 mm   2 in
<b>Length</b>	1829 mm   72.008 in
<b>System Dimensions</b>	51 mm x 51 mm (2 in x 2 in)

## Ordering Tree

# FGSB-MSHS-CB

9	10	11	
FGS	B	- MSHS - F	10

## Section Color

9	empty	yellow
	B	black

## Section Length

11	empty	6 ft
	10	10 ft
	12	12 ft

## Section Size

10	A	4 x 4 in
	B	4 x 6 in
	C	2 x 2 in
	D	4 x 4 in, slotted duct, 2 in slot spacing
	F	4 x 12 in
	F-CF	4 x 12 in, with center divider
	G	2 x 6 in
	H	4 x 24 in
	K	2 x 4 in, slotted duct, 2 in slot spacing
	STOR-B	4 x 6 in, with slack storage spools
	STOR-G	2 x 6 in, with slack storage spools
	STOR-F	4 x 12 in, with slack storage spools

## Material Specifications

**Material Type** Engineering Thermoplastic

## Environmental Specifications

**Flammability Rating** CSA S143 | UL 2024 | UL 94 V-0

**Halogen Characteristics** Blue Angel | TCO '99 | WEEE

**Safety Standard** CSA | UL

## Packaging and Weights

**Weight, net** 0.005 kg | 0.011 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



