



TDUX - Inflatable Duct Seal, Size 100

- Flexible and reliable wraparound inflatable sealing system for cables
- Fast and easy to install or remove, even when water is flowing out of the duct
- Independent of duct or cable ovality
- Water and airtight up to 50 kPa (7 psi)
- Environmentally friendly, non-toxic and resistant to chemicals


Product Classification

Regional Availability	EMEA
Product Type	Cable duct seal
Product Series	TDUX
Ordering Note	When sealing more than two cables in a duct, seperate orderable TDUX-CL clips are to be used

Dimensions

Width	120 mm   4.724 in
Length	482 mm   18.976 in
Cable Diameter, maximum	90 mm   3.543 in
Cable Diameter, minimum	45 mm   1.772 in
Conduit Inner Diameter, maximum	110 mm   4.331 in
Conduit Inner Diameter, minimum	75 mm   2.953 in

Dimension Drawing

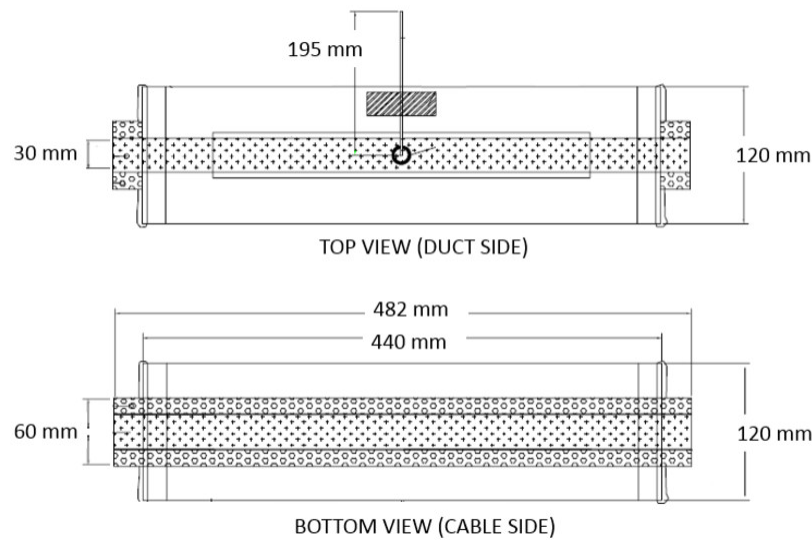

## Environmental Specifications

**Installation temperature** -5 °C to +40 °C (+23 °F to +104 °F)

## Packaging and Weights

**Included** Inflatable bladder with sealing mechanism

**Packaging quantity** 10

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

