


CL-0920-U

Universal Cable Ladder Kit, 30 in x 20 ft, 9-hole rung

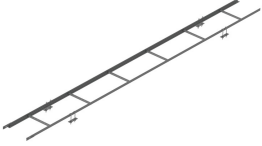

Product Classification

Product Type Ladder kit

General Specifications

Cable Runs, quantity 9

Mounting Round and angle legs

Dimensions


Height 76.2 mm | 3 in

Width 762 mm | 30 in

Length 6096 mm | 240 in

CL-0920-U

Outline Drawing

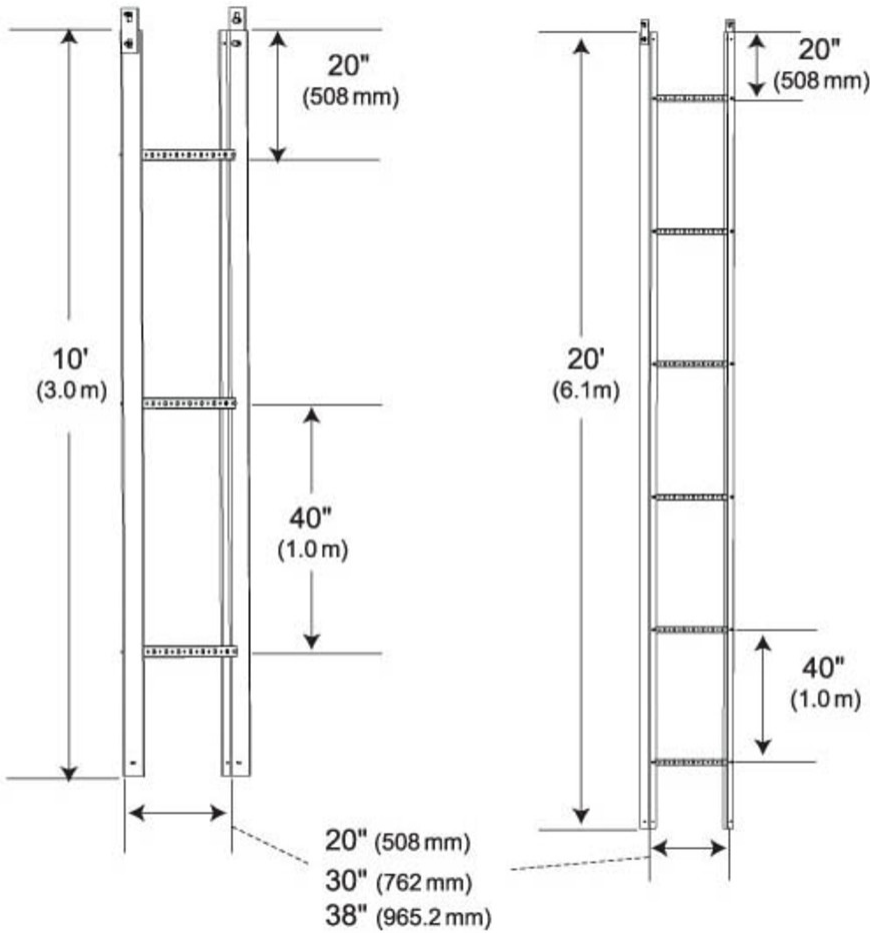

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment kits | Ladder | Splice plates

Packaging quantity 1

Weight, net 52.9 kg | 116.624 lb

Regulatory Compliance/Certifications

Agency **Classification**

CL-0920-U

ISO 9001:2015


Designed, manufactured and/or distributed under this quality management system



Included Products

- HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

HK-CL-U

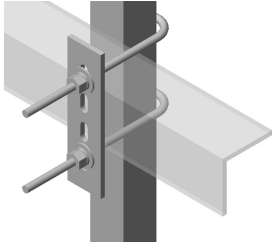

Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

Product Classification

Portfolio	CommScope®
Product Type	Ladder kit
Ordering Note	CommScope® standard product (Global)

General Specifications

Mounting	Round and angle legs
-----------------	----------------------

Dimensions

Height	203.2 mm 8 in
Width	127 mm 5 in
Length	203.2 mm 8 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	25.4 mm 1 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights

Included	J-bolts Plates
Packaging quantity	1
Weight, net	1.7 kg 3.748 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

HK-CL-U

ROHS

Compliant

UK-ROHS

Compliant

