


CL-1220-U

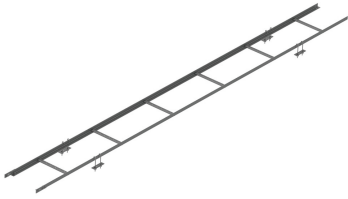

Universal Cable Ladder Kit, 38 in x 20 ft, 12-hole rung

Product Classification

Product Type Ladder kit

General Specifications

Cable Runs, quantity 12

Mounting Round and angle legs

Dimensions


Height 76.2 mm | 3 in

Width 965.2 mm | 38 in

Length 6096 mm | 240 in

CL-1220-U

Outline Drawing

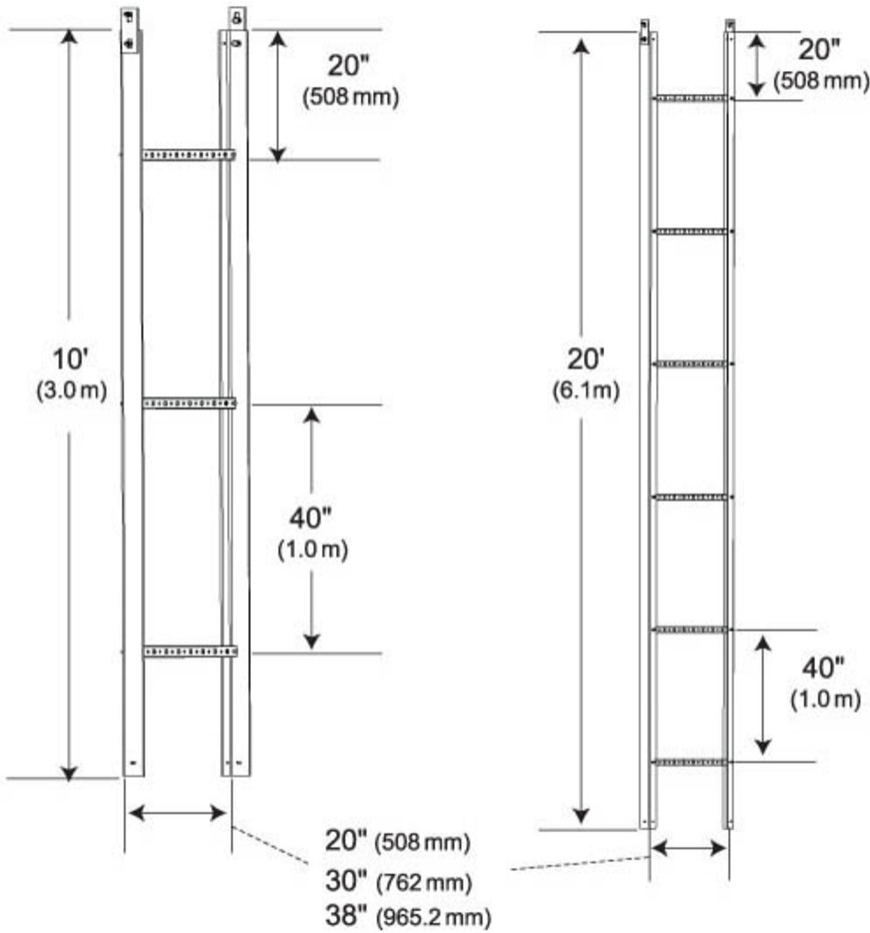

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Attachment kits | Ladder | Splice plates

Packaging quantity 1

Weight, net 55.1 kg | 121.475 lb

Regulatory Compliance/Certifications

Agency **Classification**

CL-1220-U

CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- HK-CL-U – Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

HK-CL-U



Universal Cable Ladder Hardware Kit for 1 in to 4-1/2 in round or angle members

Product Classification

Product Type	Ladder kit
Ordering Note	ANDREW® standard product (Global)

General Specifications

Cable Runs, quantity	0
Mounting	Round and angle legs

Dimensions

Height	203.2 mm 8 in
Width	127 mm 5 in
Length	203.2 mm 8 in
Mounting Diameter, maximum	114.3 mm 4.5 in
Mounting Diameter, minimum	25.4 mm 1 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Packaging and Weights

Included	J-bolts Plates
Packaging quantity	1
Weight, net	1.7 kg 3.748 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted

HK-CL-U

UK-ROHS

Compliant/Exempted

