


FPCE

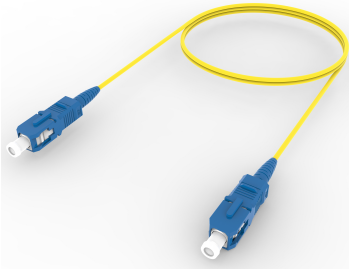

Fiber Optic Patch Cord, Simplex, Singlemode, 1.2 mm OFNP and LSZH jacket, tuned

- SC/UPC, SC/APC, LC/UPC and LC/APC connector versions
- Reduced Bend Radius fiber allows routing in electronic equipment cabinets or bays that commonly provide minimal cable management features
- Compatible with industry standard fiber cable and SC and LC connectors
- G.657.A2 rated glass
- High quality connectors
- OFNP cable

1.2 mm fiber optic patch cord assemblies, designed and tested to Telcordia GR409 requirements for small form factor cables, and GR-326 CORE mechanical and performance requirements. Also, designed and tested to the intermateability requirements of IEC 61754-4 and TIA-604-3-B.

Product Classification

Regional Availability	Europe Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, simplex
Product Series	FPCE

General Specifications


Jacket Color	Yellow
Total Fibers, quantity	1

Dimensions

Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999
Diameter Over Jacket	1.2 mm 0.047 in

Ordering Tree

FPCE

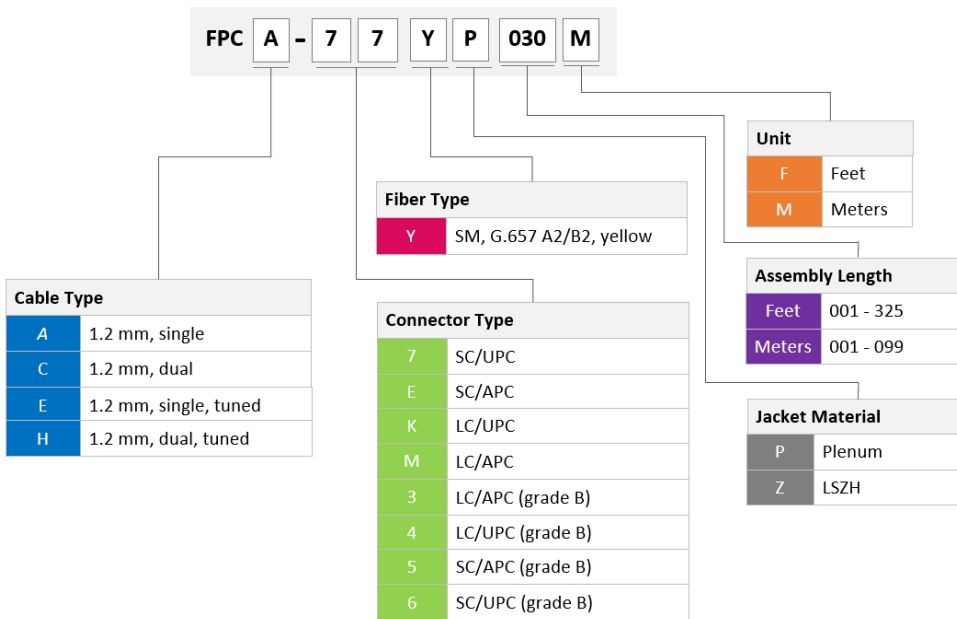

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2/B2

Environmental Specifications

Environmental Space	Low Smoke Zero Halogen (LSZH)
----------------------------	-------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---