


# WB-K410-B21

---

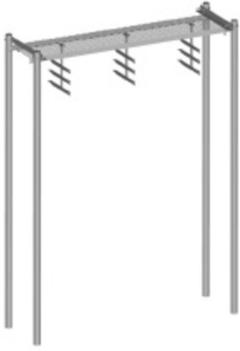

Safety Grated Waveguide Bridge Kit, 24 in x 10 ft, with four 21 ft direct burial posts

## Product Classification

**Product Type** Waveguide bridge kit

## General Specifications

**Application** Direct burial

**Cable Runs, quantity** 24

**Pipe, quantity** 4

## Dimensions

**Height** 6,400.8 mm | 252 in


**Width** 609.6 mm | 24 in

**Length** 3048 mm | 120 in

**Pipe Length** 6,400.8 mm | 252 in

# WB-K410-B21

## Outline Drawing

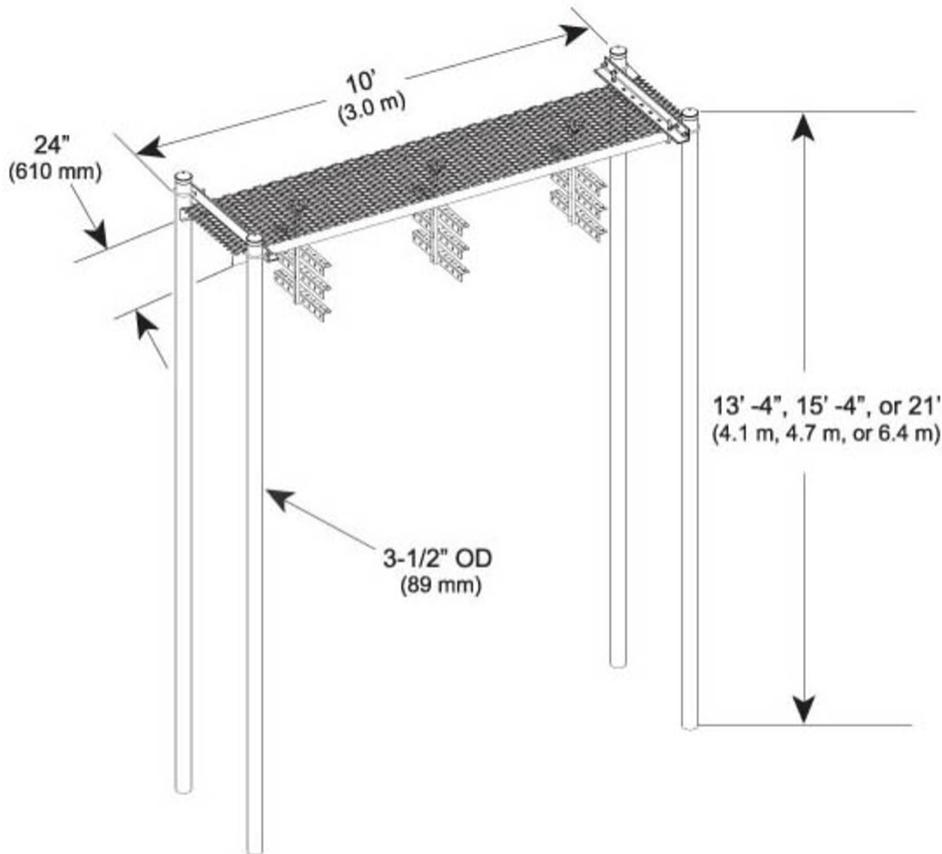

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Caps | Channel | Hardware | Posts | Support brackets | Trapeze

**Packaging quantity** 1

**Weight, net** 270.4 kg | 596.129 lb

## Regulatory Compliance/Certifications

### Agency

CHINA-ROHS

ISO 9001:2015

### Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

# WB-K410-B21

---

REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

MT-547	- Plain End Pipe, 3-1/2 in OD x 21 ft x .165" A500C 46Ksi
WB-CS24-3	- Safety Grated Channel Support, 24 in wide for 3-1/2 in OD pipe
WB-CY210	- Safety Grated Waveguide Bridge Channel, 24 in x 10 ft
WB-T24-3	- Trapeze Kit, triple tee, 24 in wide, three rungs

# MT-547

---



Plain End Pipe, 3-1/2 in OD x 21 ft x .165" A500C 46Ksi

## Product Classification

**Product Type** Plain end pipe

## General Specifications

**Pipe, quantity** 1

## Dimensions

**Height** 88.9 mm | 3.5 in

**Width** 88.9 mm | 3.5 in

**Length** 6,400.8 mm | 252 in

**Pipe Length** 6,400.8 mm | 252 in

**Pipe Outer Diameter** 88.9 mm | 3.5 in

**Material Thickness** 4.191 mm | 0.165 in

## Material Specifications

**Material Type** A500 | Hot dip galvanized steel

**Material Grade** C

**Material Strength** 46 KSI

## Packaging and Weights

**Included** Pipe

**Packaging quantity** 1


**Weight, net** 55 kg | 121.254 lb

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

# WB-CS24-3

---

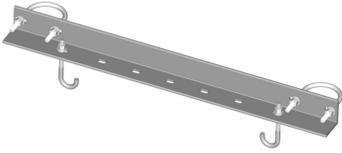

Safety Grated Channel Support, 24 in wide for 3-1/2 in OD pipe

## Product Classification

**Product Type** Support bracket

## General Specifications

**Application** Waveguide bridge kit, 24 in

**Mounting** Pipe, 88.9 mm (3-1/2 in) OD

## Dimensions


**Height** 101.6 mm | 4 in

**Width** 812.8 mm | 32 in

**Length** 101.6 mm | 4 in

# WB-CS24-3

## Outline Drawing

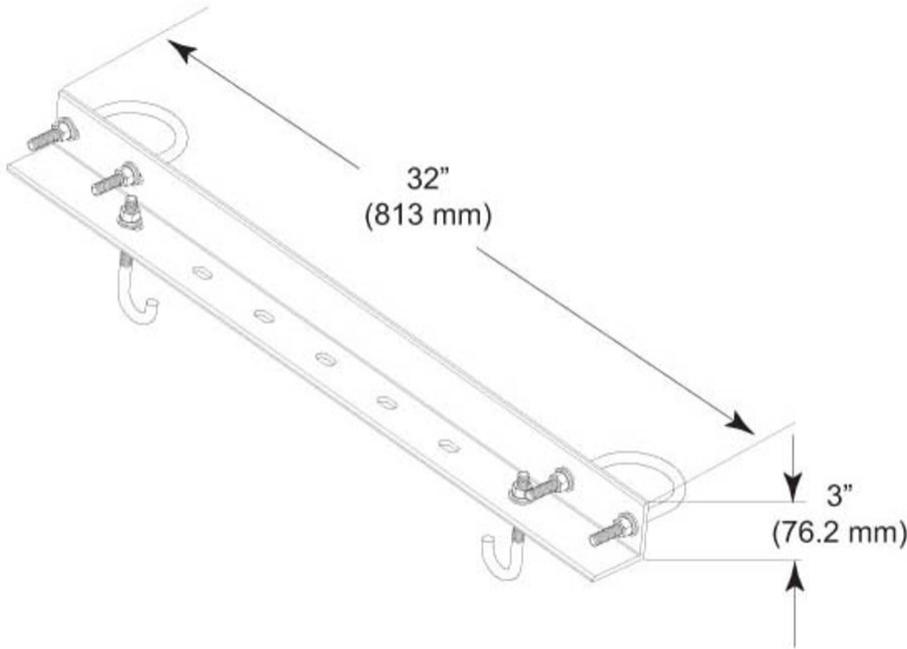

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Channel support bracket | Hardware

**Packaging quantity** 1

**Weight, net** 8.2 kg | 18.078 lb


## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



# WB-CY210

---

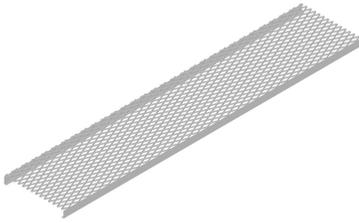

Safety Grated Waveguide Bridge Channel, 24 in x 10 ft

## Product Classification

**Product Type** Waveguide bridge channel

## General Specifications

**Application** Waveguide bridge kit, 24 in

## Dimensions


**Height** 76.2 mm | 3 in

**Width** 609.6 mm | 24 in

**Length** 3048 mm | 120 in

# WB-CY210

## Outline Drawing

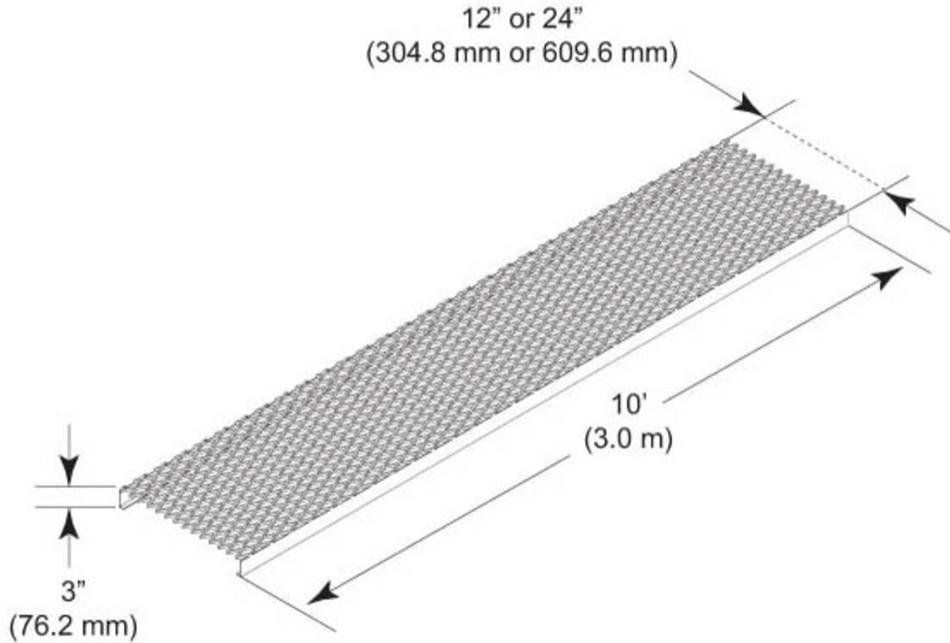

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Bridge channel

**Packaging quantity** 1

**Weight, net** 50.4 kg | 111.113 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



# WB-T24-3

---



Trapeze Kit, triple tee, 24 in wide, three rungs

## Product Classification

**Product Type** Trapeze kit

## General Specifications

**Application** Waveguide bridge kit, 24 in

**Cable Runs, quantity** 24

**Hole, quantity** 24

**Mounting** Waveguide bridge channel

**Rungs, quantity** 3

## Dimensions

**Height** 76.2 mm | 3 in


**Width** 609.6 mm | 24 in

**Length** 635 mm | 25 in

**Hole Size** 3/4 in | 7/16 in

# WB-T24-3

## Outline Drawing

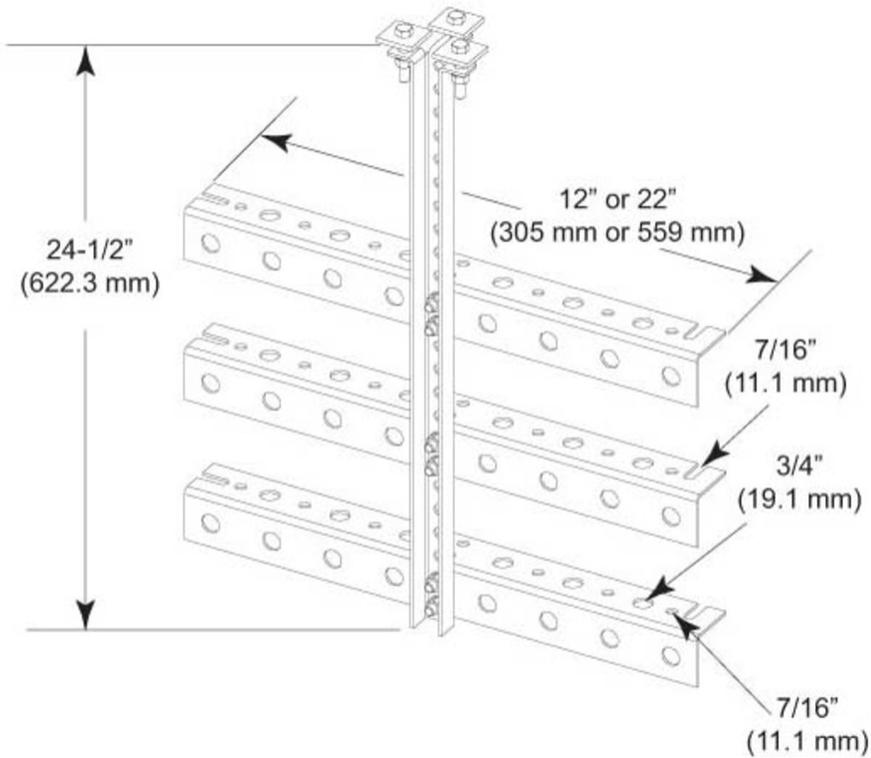

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Angle brackets | Mounting hardware

**Packaging quantity** 1

**Weight, net** 5.9 kg | 13.007 lb

## Regulatory Compliance/Certifications

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system