


WK-CNT

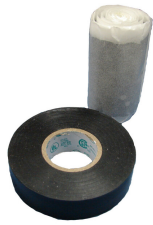

Weatherproofing Kit for Connectors and Splices, includes butyl rubber and PVC tape

Product Classification

Product Type	Weatherproofing tape
Ordering Note	CommScope® non-standard product

General Specifications

Application	Provides additional moisture seal for cable connections
Applications per Kit	Four 0.195 in to 0.195 in Four 0.240 in to 0.240 in Three 0.300 in to 0.300 in Three 0.400 in to 0.300 in Three 0.400 in to 0.400 in Two 0.400 in to 0.600 in Two 0.600 in to 0.600 in

Dimensions

Nominal Size	0.195 in 0.240 in 0.300 in 0.400 in 0.600 in
---------------------	--

Material Specifications

Material Type	Butyl rubber tape PVC tape
----------------------	------------------------------

Environmental Specifications

UV Resistance Test Method	Butyl test method in QUV weatherometer cycle of 8 hours UV at 150 °F then 4 hours of condensation at 104 °F PVC tape test method UL 510, ASTM D1000
UV Resistance, minimum with no degradation	≥1000 hours
Weather Resistance Test Method	04AS00-03.6.0 MIL-STD-1344A, Method 1002

Packaging and Weights

Height, packed	165.1 mm 6.5 in
Width, packed	50.8 mm 2 in
Length, packed	91.44 mm 3.6 in
Included	One roll of 2-1/2 in butyl rubber tape (0.06 in thick) One roll of 3/4 in PVC tape
Packaging quantity	1

WK-CNT

Weight, gross

0.36 kg | 0.794 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant

UK-ROHS

Compliant



Included Products

- 42615-10 - Butyl Rubber Tape, 24 in
- 9905-41 - Black 3/4 in PVC Tape, 66 ft



Butyl Rubber Tape, 24 in

Product Classification

Product Type	Weatherproofing tape
Ordering Note	CommScope® non-standard product

General Specifications

Application	Provides additional moisture seal for cable connections
Applications per Kit	One 1/2 in–2-1/4 in One 1/2 in–7/8 in One 1/2 in–7/8 in to device Two 1/2 in–1/2 in
Color	Black

Dimensions

Width	63.5 mm 2.5 in
Length	609.6 mm 24 in
Nominal Size	1-1/4 in 1-5/8 in 1/2 in 1/4 in 2-1/4 in 3/8 in 5/8 in 7/8 in

Material Specifications

Material Type	Butyl rubber tape
----------------------	-------------------

Environmental Specifications

UV Resistance Test Method	Butyl test method in QUV weatherometer cycle of 8 hours UV at 150 °F then 4 hours of condensation at 104 °F
UV Resistance, minimum with no degradation	≥1000 hours
Weather Resistance Test Method	04AS00-03.6.0 MIL-STD-1344A, Method 1002

Packaging and Weights

Height, packed	63.5 mm 2.5 in
Width, packed	71.12 mm 2.8 in
Length, packed	25.4 mm 1 in

42615-10

Packaging quantity 1
Weight, gross 0.17 kg | 0.375 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015



Classification

Designed, manufactured and/or distributed under this quality management system

9905-41



Black 3/4 in PVC Tape, 66 ft

Product Classification

Product Type	Weatherproofing tape
Ordering Note	CommScope® non-standard product

General Specifications

Application	Provides additional moisture seal for cable connections
Applications per Kit	Four 1/2 in–1/2 in Four 1/2 in–7/8 in to device One 1/2 in–2-1/4 in Two 1/2 in–7/8 in
Color	Black

Dimensions

Width	19.05 mm 0.75 in
Length	20,116.801 mm 792 in
Nominal Size	1-1/4 in 1-5/8 in 1/2 in 1/4 in 2-1/4 in 3/8 in 5/8 in 7/8 in

Material Specifications

Material Type	PVC tape
----------------------	----------

Environmental Specifications

UV Resistance Test Method	PVC tape test method UL 510, ASTM D1000
Weather Resistance Test Method	04AS00-03.6.0 MIL-STD-1344A, Method 1002

Packaging and Weights

Height, packed	60.96 mm 2.4 in
Width, packed	60.96 mm 2.4 in
Length, packed	20.32 mm 0.8 in
Packaging quantity	1
Weight, gross	0.11 kg 0.243 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system