


A-101430

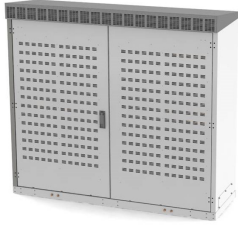

Bowler E/// cab w/o diplexors

- Sealed to outside environment

Bowler Ericsson cabinet without diplexors

Product Classification

Product Type Outdoor cabinet

General Specifications

Access Double door

Accessories Cable plate | External alarm connection | Hangers | In-ground root | Plinth

Cabinet Type Combiner cabinet | Radio cabinet

Cable Entry Location Bottom left | Bottom right

Color Green (RAL 6009) | Light Gray (RAL 7035) | Others available at additional cost

Door Security Internal door contact | Swing handle with 22mm profile cylinder

Door Type, front Double hinged | Key lock (included!) | Non-removable

Door, quantity 2

Front Door Type Double hinged

Radios Included None

Dimensions

Height 1,751.838 mm | 68.97 in

Width 1,899.92 mm | 74.8 in

Depth 659.892 mm | 25.98 in

Material Specifications

Finish Powder coated

Material Type Galvanized steel

Packaging and Weights

Weight, net 35.834 kg | 79 lb