


# BLK-RLBT-A06060

---

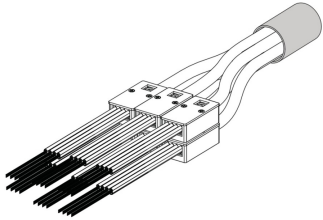

Fiber Optic Ribbon Breakout Kit, 12F/ribbon, 72F/tube, 6 breakout legs, 6 tubes/leg

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Product Type</b>	Fiber breakout kit, rectangular
<b>Product Series</b>	BLK-R

## General Specifications

<b>Application</b>	For use with ribbon fiber cables
<b>Breakout Legs, quantity</b>	6
<b>Fibers per Ribbon, maximum</b>	12
<b>Fibers per Tube, maximum</b>	72
<b>Tube Type</b>	Ribbon in loose buffer tube
<b>Tubes per Leg, quantity</b>	6

## Dimensions

<b>Tube Length</b>	5,001.26 mm   196.9 in
--------------------	------------------------

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
----------------------------	---------

## Packaging and Weights

<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant

# BLK-RLBT-A06060

---

UK-ROHS

Compliant

