


# FST-D-MT-AC

---

Fiber Optic Splice Tray, 24 splice capacity, ribbon mass fusion

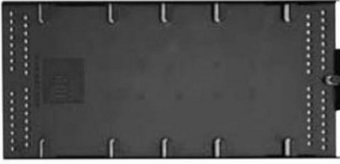

## Product Classification

**Regional Availability** Latin America | North America  
**Product Type** Fiber splice tray

## General Specifications

**Application** For use with FDF splice panels  
**Color** Black  
**Splicing Capacity, maximum** 24  
**Splicing Type** Mass fusion, ribbon

## Environmental Specifications

**Storage Temperature** -40 °C to +85 °C (-40 °F to +185 °F)

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

