


UKXMPMXAD

Base Product

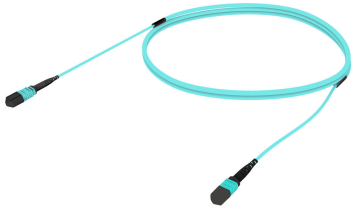

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 12-Fiber, Low Smoke Zero Halogen (LSZH)

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

UKXMPMXCD

Ultra Low Loss (ULL) Multimode OM4 MPO12 (Unpinned) to MPO12 (Pinned), Armored Pre-terminated Trunk Cable, 12-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability

Asia | Australia/New Zealand | Latin America | Middle East/Africa | North America

Portfolio

CommScope®

Product Type

Fiber trunk cable assembly

Product Brand

SYSTEMAX ULL

Ordering Note

For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration | Not available in the United States or Canada

General Specifications

Connector A, quantity

1

Color, boot A

Black

Color, connector A

Aqua

Connector B, quantity

1

Color, boot B

Black

Color, connector B

Aqua

Construction Type

Armored | Stranded

Furcation Color

Aqua


UKXMPMXAD

Interface, Connector A	MPO-12/UPC Female
Interface Feature, connector A	Unpinned
Interface, Connector B	MPO-12/UPC Male
Interface Feature, connector B	Pinned
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

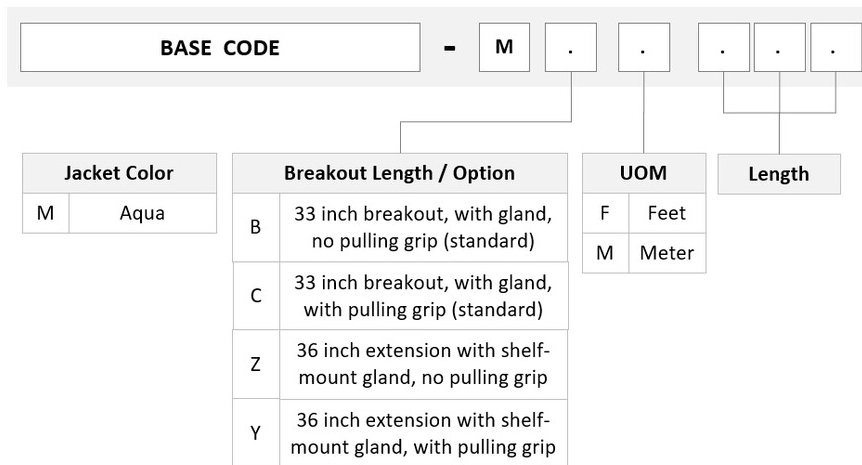

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

UKXMPMXAD

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760120055	-	Fiber indoor cable, LazrSPEED® Riser/LSZH rated, MPO Trunk, interlocking aluminum armored, Multimode OM4, 12 fiber, Gel-free, Feet jacket marking, Aqua jacket color
N-012-MZ-5K-F12AQ		
860366210	-	MPO12, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
860366228	-	MPO12, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3mm