


ARGQPCSJ8

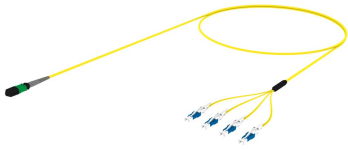

Singlemode MPO8 (Unpinned) to CS/UPC 8-Fiber Low Smoke Zero Halogen Array Cord

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber array cable assembly
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, boot B	Blue
Color, connector A	Green
Color, connector B	Blue
Construction Type	Stranded
Fibers per Subunit, quantity	8
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Female
Interface, Connector B	CS/UPC
Jacket Color	Yellow
Polarity	Method A
Total Fibers, quantity	8

Dimensions

Breakout Length	10 in
Cable Assembly Length Range (m)	1 – 305
Cable Assembly Length Range (ft)	10 – 999

ARGQPCSJ8

Ordering Tree

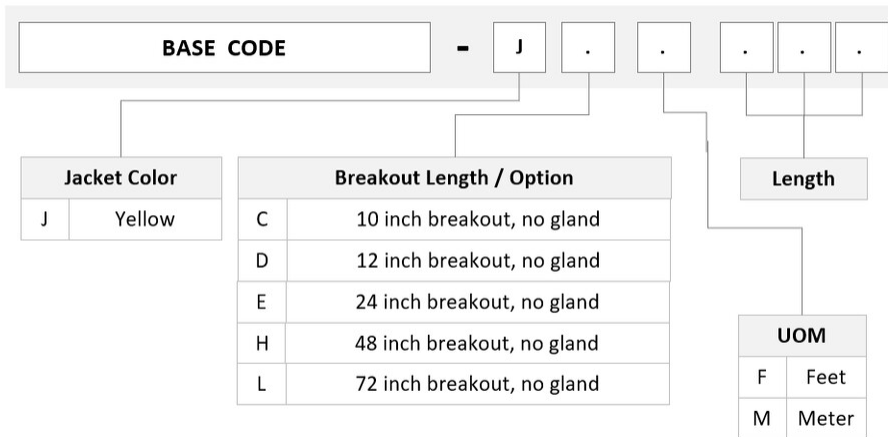

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Included Products

- 760237972 – Low Smoke Zero Halogen Riser Light Duty MPO Patchcord Cable, 12 N-012-MP-8G1-F30YL/D fiber
- 860637706 – MPO8, ULTRA LOW LOSS, FEMALE, SM, GREEN, 3mm