


# URXRVP7R

## Base Product

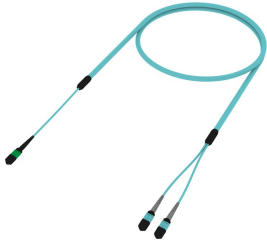

Ultra Low Loss OM4, 16F MM APC MPO (Unpinned) to 8F MPO (Unpinned), Fiber Extension Cable Assembly, 16-Fiber, Dual rate (LSZH /RISER)

## Product Classification

<b>Regional Availability</b>	Australia/New Zealand   Europe   Latin America   Middle East/Africa
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber array cable assembly
<b>Product Brand</b>	Propel
<b>Ordering Note</b>	Can only be used with CXP transceivers   For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications


<b>Color, boot A</b>	Red
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Black
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-16/APC Female
<b>Interface Feature, connector A</b>	QSFP configuration
<b>Interface, Connector B</b>	MPO-08/UPC Female
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	16

## Dimensions

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

# URXRVQP7R

## Ordering Tree

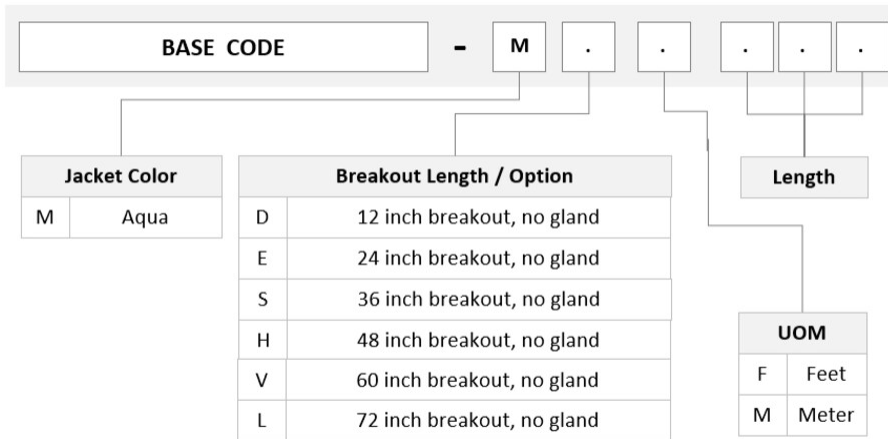

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode | Multimode

**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser | Indoor

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



## Included Products

760251055

# URXRVQP7R

---

- N-016-MP-5K-F30AQ/D – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser Light Duty for MPO Patchcords, 16 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, Dca flame rating
- 860633307 – MPO8, ULTRA LOW LOSS, FEMALE, OM3/4, AQUA, 3mm
- 860659159 – Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, non-pinned, green, for 3 mm cable