


# UJGRXR8N

## Base Product

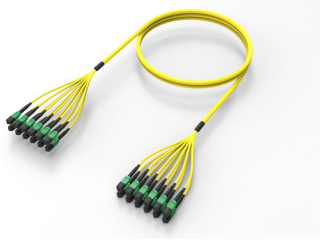

Ultra Low Loss (ULL) Singlemode G.657.A2 MPO16 (Pinned) to MPO16 (Pinned), Fiber Trunk Cable Assembly, 192-Fiber, Dual Rated (OFNR /LSZH)

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Fiber trunk cable assembly   |
| <b>Product Brand</b>         | Propel   SYSTIMAX ULL  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Connector A, quantity</b>        | 12                      |
| <b>Color, boot A</b>                | Black                   |
| <b>Color, connector A</b>           | Green                   |
| <b>Connector B, quantity</b>        | 12                      |
| <b>Color, boot B</b>                | Black                   |
| <b>Color, connector B</b>           | Green                   |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Yellow                  |
| <b>Interface, Connector A</b>       | MPO-16/APC Male         |
| <b>Interface, Connector B</b>       | MPO-16/APC Male         |
| <b>Jacket Color</b>                 | Yellow                  |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 16                      |
| <b>Total Fibers, quantity</b>       | 192                     |

## Dimensions

# UJGRXR8N

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 22 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree



## Mechanical Specifications

|  |                                 |
|--|---------------------------------|
| <b>Cable Retention Strength, maximum</b> | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|--|---------------------------------|

## Optical Specifications

|                   |                      |
|-------------------|----------------------|
| <b>Fiber Mode</b> | Singlemode           |
| <b>Fiber Type</b> | G.657.A2, TeraSPEED® |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>Environmental Space</b>   | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant/Exempted   |

# UJGRXR8N

---



## Included Products

- 760251080  
N-192-MP-8G1-F16YL/30T/B2 - Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 192 fiber with 16-fiber, 3.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860661398 - Fiber Optic Connector Kit, singlemode, OS2, MPO-16/APC, ULL, pinned, green, for 3 mm cable