


URVRVMPAH

Base Product

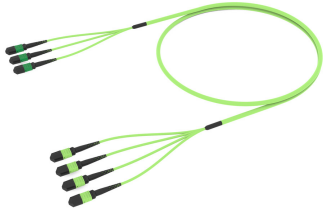

Ultra Low Loss (ULL) OM5, 3X4, MPO16 Multimode APC (Non-Pinned) to MPO12 (Non-Pinned), 48-Fiber, Conversion Array, LSZH

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber conversion array cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	3
Color, boot A	Black
Color, connector A	Green
Connector B, quantity	4
Color, boot B	Black
Color, connector B	Lime green
Construction Type	Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-16/APC Female
Interface, Connector B	MPO-12/UPC Female
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	48

Dimensions


Breakout Length	12 in 24 in 36 in 48 in 60 in 72 in
------------------------	-----------------------------------------------

URVRVMPAH

Cable Assembly Length Range (m) 2 – 305

Cable Assembly Length Range (ft) 4 – 999

Ordering Tree

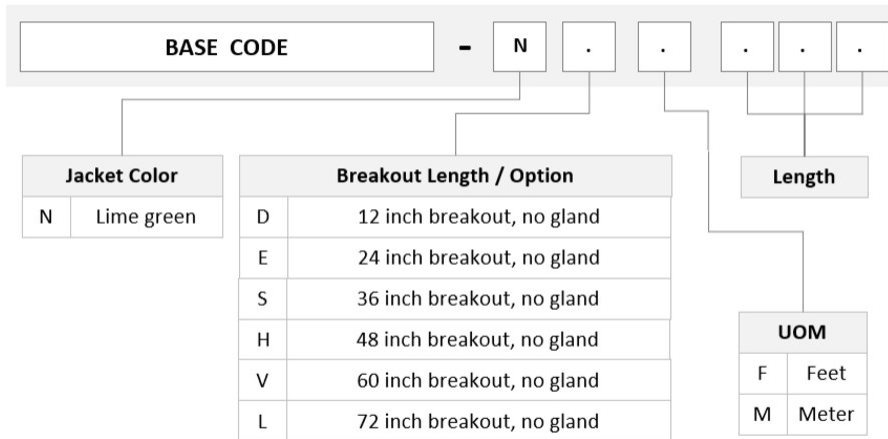

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM5, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

URVRVMPAH



Included Products

- | | | |
|----------------------------------|---|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| 760229070
N-048-MP-5G-F12LM/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 48 fiber multi-unit with 12 fiber subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, Dca flame rating |
| 860617232 | - | MPO12, ULTRA LOW LOSS, FEMALE, OM5, LIME, 3mm |
| 860659159 | - | Fiber Optic Connector Kit, multimode, OM3/OM4, MPO-16/APC, ULL, non-pinned, green, for 3 mm cable |