

FSXLCLCW6

LazrSPEED® 550 LC/UPC to LC/UPC, Distribution Cable, 6-Fiber, Plenum

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications


Cable Glands	No glands
Color, connector A	Beige
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	7 – 999

Ordering Tree

FSXLCLCW6

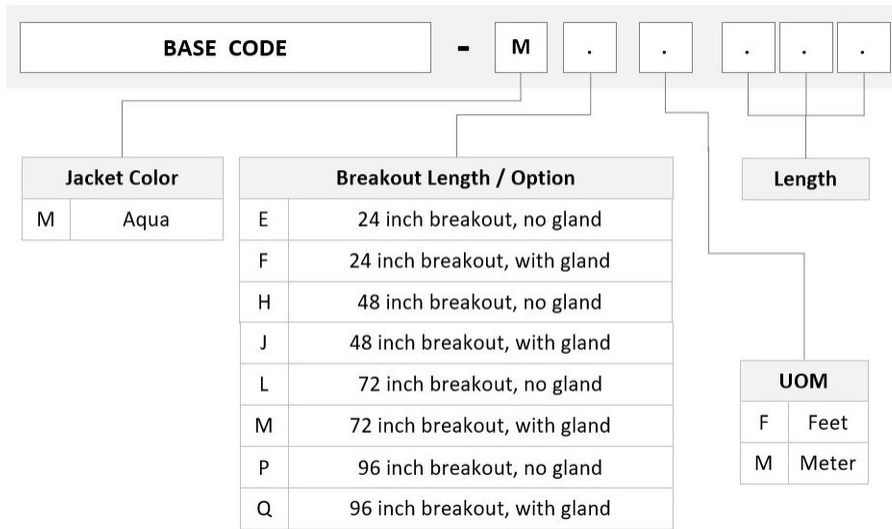

Mechanical Specifications

Cable Retention Strength, maximum	0.50 lb @ 0 ° 0.50 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Mode Multimode

Fiber Type	OM4, LazrSPEED®
-------------------	-----------------

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)

Environmental Space Plenum

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

UK-ROHS

Classification

Above maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant/Exempted

Compliant/Exempted



Included Products

FSXLCLCW6

460125271	-	Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, multimode
760012138	-	Fiber indoor cable, LazrSPEED® Plenum Distribution Cable, 6 fiber single-unit, Multimode OM4,
P-006-DS-5K-FSUAQ		Feet jacket marking, Aqua jacket color