


CB-12-50

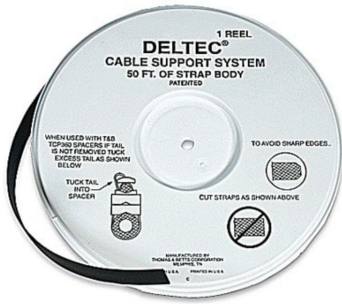

Cable Banding, Bulk, 1/2 in x 50 ft Reel (uses CB-LH-25 Locking Heads - not incl)

Product Classification

Product Type	Banding
Ordering Note	CommScope® standard product in the United States and Canada

General Specifications

Adapter Type	Adapter
Color	Black
Mounting	Round member

Dimensions

Width	12.7 mm 0.5 in
Length	15.24 m 50 ft
Material Thickness	1.524 mm 0.06 in

Material Specifications

Material Type	Heat-stabilized weather resistant acetal
----------------------	--

Environmental Specifications

Operating Temperature	-65 °C to +90 °C (-85 °F to +194 °F)
------------------------------	--------------------------------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CSA	Compliant

CB-12-50

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

