


MC-RR1050-3

Three Sector Dual Radio Ring Mount

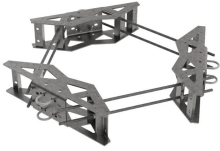

Product Classification

Product Type Universal ring mount

General Specifications

Mounting Monopole, 254–1270 mm (10–50 in) OD

Pipe, quantity 0

Sectors, quantity 3

Dimensions

Height 203.2 mm | 8 in

Length 152.4 mm | 6 in

Mounting Diameter, maximum 1270 mm | 50 in

Mounting Diameter, minimum 254 mm | 10 in

Pipe Outer Diameter 0 mm | 0 in

Mounting Circumference, maximum 3,990.34 mm | 157.1 in

Mounting Circumference, minimum 797.56 mm | 31.4 in

Material Specifications

Material Type Hot dip galvanized steel

Packaging and Weights

Included Hardware | Mount

Packaging quantity 1

Weight, net 45.722 kg | 100.8 lb