

Indoor/Outdoor Low Smoke Zero Halogen, TeraSPEED® Central Loose Tube Fiber Optic Cable, 6-fiber, Singlemode OS2, Gel-free, black. Provides Rodent Resistance.

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber indoor/outdoor cable
<b>Product Series</b>	C-CN


## General Specifications

<b>Cable Type</b>	Loose tube
<b>Subunit Type</b>	Gel-free
<b>Jacket Color</b>	Black
<b>Jacket Marking</b>	Meters
<b>Jacket Marking Method</b>	Inkjet
<b>Jacket Marking Text</b>	COMMSCOPE GB OPTICAL CABLE 760254738 INT/EXT RODENT RESISTANT DLT 6X9/125 OS2 EN50575 CLASS D (Serial NUMBER) (METRE MARK)
<b>Fibers per Subunit, quantity</b>	6
<b>Total Fiber Count</b>	6

## Dimensions

<b>Cable Length</b>	4000 m   13,123.36 ft
<b>Diameter Over Jacket</b>	6.4 mm   0.252 in

## Representative Image

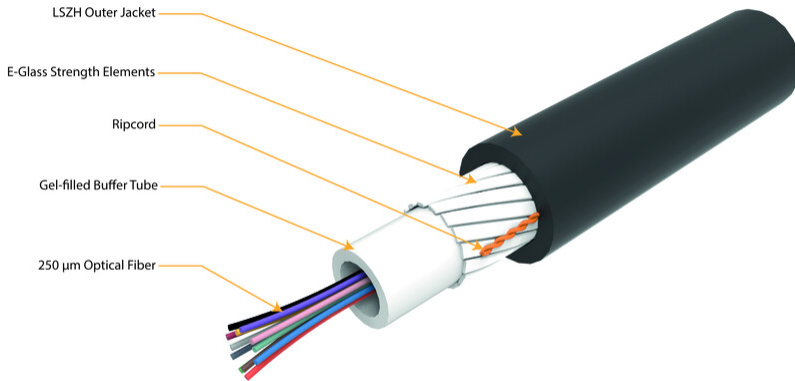

## Mechanical Specifications

<b>Minimum Bend Radius, loaded</b>	139.7 mm   5.5 in
<b>Minimum Bend Radius, unloaded</b>	129.5 mm   5.098 in
<b>Tensile Load, long term, maximum</b>	650 N   146.126 lbf
<b>Tensile Load, short term, maximum</b>	1250 N   281.011 lbf

## Optical Specifications

<b>Fiber Type</b>	OS2
-------------------	-----

## Optical Specifications, Wavelength Specific

<b>Attenuation, maximum</b>	0.35 dB/km @ 1,300 nm   0.35 dB/km @ 1,550 nm   0.45 dB/km @ 1,310 nm
-----------------------------	---

<b>Standards Compliance</b>	IEC 60794-1   TIA-492CAAB (OS2)
-----------------------------	---------------------------------

## Environmental Specifications

<b>Installation temperature</b>	-5 °C to +50 °C (+23 °F to +122 °F)
<b>Operating Temperature</b>	-10 °C to +70 °C (+14 °F to +158 °F)
<b>Storage Temperature</b>	-10 °C to +70 °C (+14 °F to +158 °F)
<b>EN50575 CPR Cable EuroClass Fire Performance</b>	Dca
<b>EN50575 CPR Cable EuroClass Smoke Rating</b>	s2
<b>EN50575 CPR Cable EuroClass Droplets Rating</b>	d2

# 760254738 | C-006-CN-8W-M06BK/28D/GY/D

---

**EN50575 CPR Cable EuroClass Acidity Rating** a1  
**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Packaging and Weights

**Cable weight** 47 kg/km | 31.583 lb/kft

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant



## Included Products

CS-8W-LT - TeraSPEED® G652D/G657A1 Singlemode Fiber

## \* Footnotes

**Operating Temperature** Specification applicable to non-terminated bulk fiber cable