


PGP-CS10

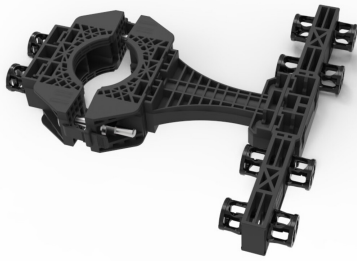

Polymer PIM-Guard® Antenna and RRU Cable Support Bracket with 10 positions / 20 cables for stackable hangers (up to 2 per position)

Compatible with first and second generation Polymer PIM-Guard products

-SSH-1416

-SSH-411

-SSH-1117

Product Classification

Product Type Antenna/RRU Cable Support

Product Brand PIM-Guard®

General Specifications

Cable Runs, quantity 10

Hole, quantity 10

Mounting Round member

Dimensions

Height 50.8 mm | 2 in

Width 304.8 mm | 12 in

Length 304.8 mm | 12 in


Mounting Diameter, maximum 60.96 mm | 2.4 in

Mounting Diameter, minimum 60.96 mm | 2.4 in

Hole Size 3/4 in

Ordering Tree

PGP-CS10

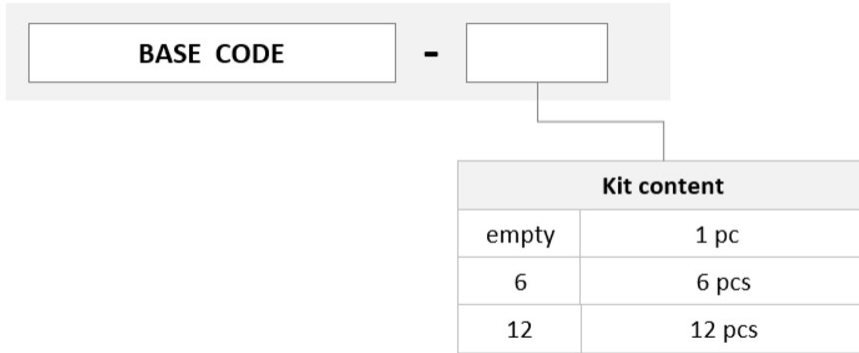

Material Specifications

Material Type Polymer

Packaging and Weights

Packaging quantity 1

Weight, net 0.82 kg | 1.808 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

