


# U3V2X2XVF

## Base Product

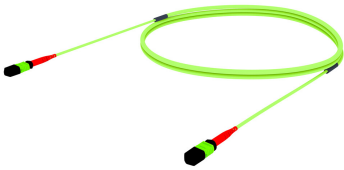

Ultra Low Loss (ULL) LazrSPEED® 550 OM5 MPO/24 (Pinned) to MPO/24 (Pinned), Pre-terminated Cable, MPO24, 24-Fiber, LSZH

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Europe   Middle East/Africa                  |
| <b>Portfolio</b>             | CommScope®                                   |
| <b>Product Type</b>          | Fiber trunk cable assembly                   |
| <b>Product Brand</b>         | SYSTIMAX ULL                                 |
| <b>Ordering Note</b>         | Not available in the United States or Canada |

## General Specifications


|                                     |                         |
|-------------------------------------|-------------------------|
| <b>Color, connector A</b>           | Lime green              |
| <b>Color, connector B</b>           | Lime green              |
| <b>Construction Type</b>            | Stranded                |
| <b>Furcation Color</b>              | Lime green              |
| <b>Interface, Connector A</b>       | MPO-24/UPC Male         |
| <b>Interface, Connector B</b>       | MPO-24/UPC Male         |
| <b>Jacket Color</b>                 | Lime green              |
| <b>Polarity</b>                     | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b> | 24                      |
| <b>Total Fibers, quantity</b>       | 24                      |

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 33 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree

# U3V2X2XVF

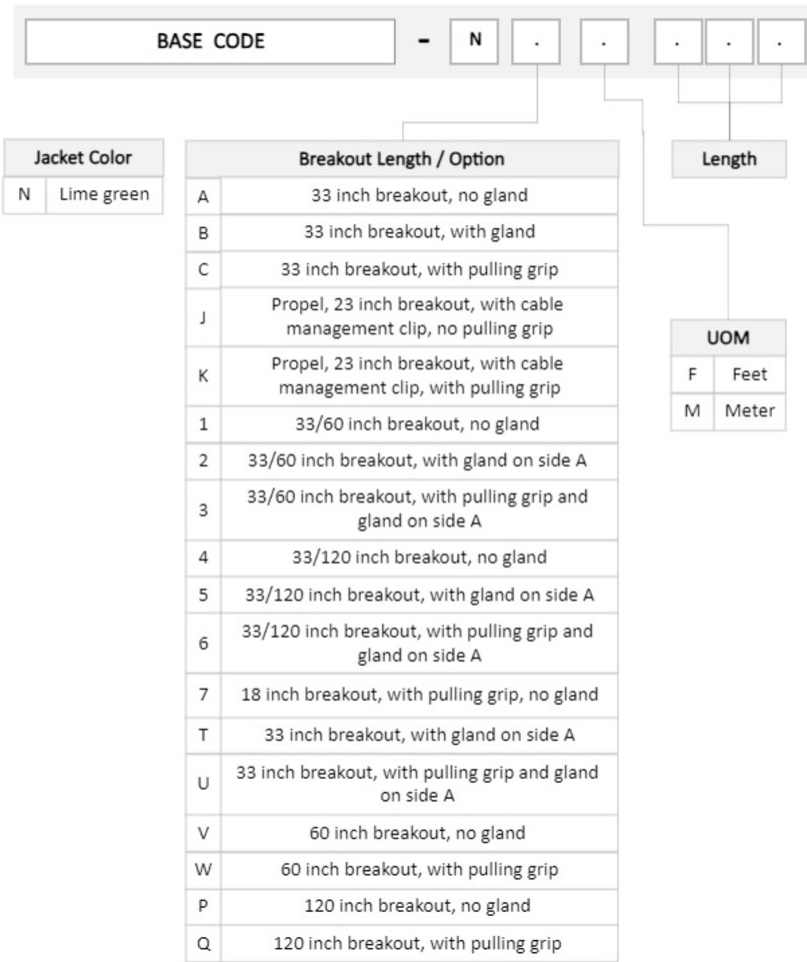

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

**Agency**                      **Classification**

# U3V2X2XVF

---

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

## Included Products

- 760253233  
N-024-MP-5G-F24LM/30T/B2 – Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber with 24-fiber, 3.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, B2ca flame rating
- 860662280 – MPO24,MALE,OM5,LIME,3.0MM