


FGSB-ACC001

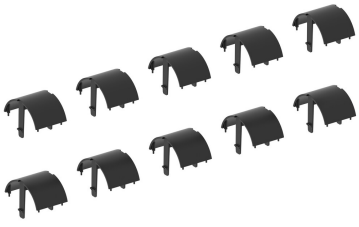

FiberGuide® Express Exit Removable Blank Insert, Kit of 10, Black

Product Classification

| | |
|------------------------------|---|
| Regional Availability | Asia Australia/New Zealand EMEA Latin America North America |
| Portfolio | CommScope® |
| Product Type | Accessory |
| Product Brand | FiberGuide® |
| Product Series | FGS |

General Specifications

| | |
|------------------------|------------|
| Product Feature | Round |
| Color | Black |
| Orientation | Horizontal |
| Section Type | Accessory |

Dimensions

| | |
|--------------------------|-------------------------------|
| Height | 68.58 mm 2.7 in |
| Width | 66.04 mm 2.6 in |
| Length | 99.06 mm 3.9 in |
| System Dimensions | 102 mm x 102 mm (4 in x 4 in) |

Ordering Tree

FGSB-ACCO01

FGS ⁹ B - MEXP - ¹⁰ A/B/F

Section Color

| | | |
|---|-------|--------|
| 9 | empty | yellow |
| | B | black |

Section Size

| | | |
|----|-----------|--|
| 10 | A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit |
| | E-A/B/F | 4 x 4/6/12 in, with 4 x 4 in exit |
| | F-F/H-NC | 4 x 12/18/24 in, with 4 x 12 in exit, no cover |
| | G-A/B/F | 4 x 4/6/12 in, with 4 x 6 in exit |
| | LP-A/B/F | 4 x 4/6/12 in, with 2 x 2 in exit, low profile |
| | LP-CA | 4 x 4/6/12 in, with 2 x 4 in exit, low profile |
| | LP-G | 2 x 6 in, with 2 x 2 in exit, low profile |
| | GS-ABF-NC | 4 x 4/6/12 in, with 4 x 6 in exit, no cover |
| | CV | cover |
| NC | no cover | |

Material Specifications

Material Type Engineering Thermoplastic

Environmental Specifications

Flammability Rating CSA S143 | UL 2024 | UL 94 V-0

Halogen Characteristics Blue Angel | TCO '99 | WEEE

Safety Standard CSA | UL

Packaging and Weights

Included Hardware

Packaging quantity 10

Weight, net 0.431 kg | 0.95 lb