


WSC-SB032410

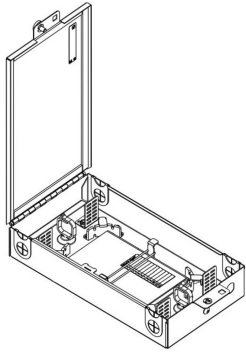

WSC Wall Splice Cabinet for MDU applications, indoor/outdoor, for up to 24 fibers, includes 2 splice trays with mechanical ribbon, no key lock

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber wall box

General Specifications

Functionality	Splicing
Access	Front
Enclosure Color	Putty white
Front Cover Type	Hinged at top
Interface	Splicing only
Lock Type	Locking bolt
Mounting	Wall
Splice Trays	Included
Splicing Type	Mechanical, mass fusion

Dimensions

Height	345 mm 13.583 in
Width	185 mm 7.283 in
Depth	65 mm 2.559 in

Environmental Specifications

Environmental Space	Outdoor
Qualification Standards	NEMA, Type 4

WSC-SB032410

Packaging and Weights

Packaging quantity 1
Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

