


# P40-278X174

---

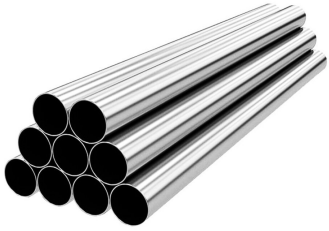

VZWSMART 174" PIPE 2.5 SCH40 (2.875" OD X 0.203" THK)

## Product Classification

<b>Product Type</b>	Plain end pipe
<b>Ordering Note</b>	ANDREW® non-standard product
<b>Warranty</b>	One year

## General Specifications

**Pipe, quantity** 1

## Dimensions

<b>Length</b>	4,419.6 mm   174 in
<b>Pipe Length</b>	4,419.6 mm   174 in
<b>Pipe Outer Diameter</b>	73.025 mm   2.875 in
<b>Material Thickness</b>	5.156 mm   0.203 in

## Material Specifications

<b>Material Type</b>	A500   Hot dip galvanized steel
<b>Material Grade</b>	C

## Packaging and Weights

<b>Included</b>	Pipe
<b>Packaging quantity</b>	1
<b>Weight, net</b>	37.65 kg   83.004 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

# P40-278X174

---



\* Footnotes

**Warranty**

For more information, please consult our Product Warranty guidelines