


# UNXQVLUT8

## Base Product

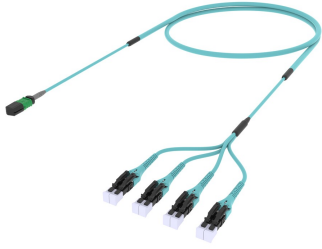

Ultra Low Loss ULL OM4 MPO8 APC non-pinned to LC/UPC Uniboot Ruggedized fanout Cable, 8-Fiber, Dual Rated (OFNR/LSZH), 8 fiber PmP 2.0 mm

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America   |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | Propel   SYSTIMAX ULL  |
| <b>Ordering Note</b>         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                       |                         |
|---------------------------------------|-------------------------|
| <b>Connector A, quantity</b>          | 1                       |
| <b>Color, boot A</b>                  | Gray                    |
| <b>Color, connector A</b>             | Aqua                    |
| <b>Connector B, quantity</b>          | 8                       |
| <b>Color, boot B</b>                  | Aqua                    |
| <b>Color, connector B</b>             | Black                   |
| <b>Construction Type</b>              | Stranded                |
| <b>Furcation Color</b>                | Aqua                    |
| <b>Interface, Connector A</b>         | MPO-08/APC Female       |
| <b>Interface, Connector B</b>         | LC/UPC                  |
| <b>Interface Feature, connector B</b> | Uniboot                 |
| <b>Jacket Color</b>                   | Aqua                    |
| <b>Polarity</b>                       | Method B Enhanced (ULL) |
| <b>Fibers per Subunit, quantity</b>   | 8                       |
| <b>Total Fibers, quantity</b>         | 8                       |

# UNXQVLUT8

## Dimensions

|   |          |
|---|----------|
| <b>Breakout Length</b>                  | 22 in    |
| <b>Cable Assembly Length Range (m)</b>  | 3 – 305  |
| <b>Cable Assembly Length Range (ft)</b> | 10 – 999 |

## Ordering Tree

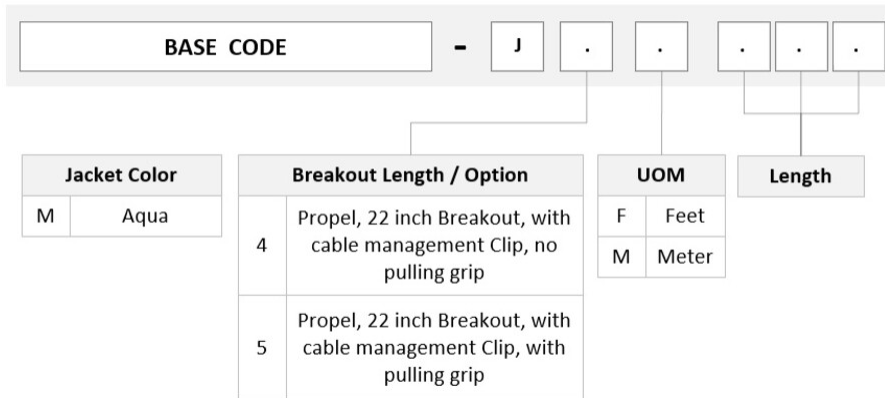

## Mechanical Specifications

|  |                                 |
|--|---------------------------------|
| <b>Cable Retention Strength, maximum</b> | 11.24 lb @ 0 °   4.40 lb @ 90 ° |
|--|---------------------------------|

## Optical Specifications

|                   |                 |
|-------------------|-----------------|
| <b>Fiber Mode</b> | Multimode       |
| <b>Fiber Type</b> | OM4, LazrSPEED® |

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -10 °C to +60 °C (+14 °F to +140 °F) |
| <b>Environmental Space</b>   | Dual Rated LSZH/Riser   Indoor       |

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system   |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |

# UNXQVLUT8

---

UK-ROHS

Compliant/Exempted



## Included Products

- |                                      |   |   |
|--------------------------------------|---|---|
| 760248162<br>N-008-MP-5K-F08AQ/20T/D | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, 8 fiber, Multimode OM4, Feet jacket marking, Aqua jacket color, Dca flame rating |
| 860658161                            | - | 2.0 mm LC/UPC Uniboot GEN 1.5, Aqua   |
| 860662232                            | - | MPO8,ULL,Multimode,FEMALE,APC,GREEN,2 mm  |