


UHVQZQZTU

Base Product

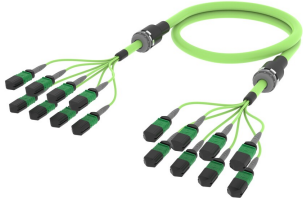

Ultra Low Loss (ULL) OM5 MPO8 APC (pinned) to MPO8 APC (pinned) Fiber Trunk Cable Assembly, 64-Fiber, Armored Indoor Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	Propel SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Connector A, quantity	8
Color, boot A	Gray
Color, connector A	Green
Connector B, quantity	8
Color, boot B	Gray
Color, connector B	Green
Construction Type	Armored Stranded
Furcation Color	Lime green
Interface, Connector A	MPO-08/APC Male
Interface, Connector B	MPO-08/APC Male
Jacket Color	Lime green
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	64

Dimensions

Breakout Length	22 in
------------------------	-------

UHVQZQZTU



Included Products

760256048
P-064-MZ-5G-F08LM/20T

- Fiber indoor cable, LazrSPEED® Plenum MPO Trunk, interlocking aluminum armored with plenum jacket, Multimode OM5, 64 fiber multi-unit with 8 fiber subunits, Lime-green jacket color, Feet cable marking

860662230

- MPO8,ULL,Multimode,MALE,APC,GREEN,2 mm