


FPS-G2ACCFNOUT32

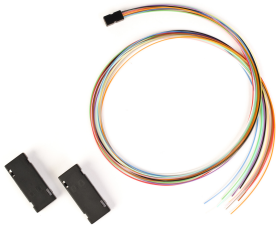

Splitter fanout kit 3x32

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber breakout kit, rectangular

General Specifications

Color	Black
Compatible Interface	LC LC, keyed SC ST

Dimensions

Height	7.62 mm 0.3 in
Width	17.78 mm 0.7 in
Length	43.18 mm 1.7 in
Tube Length	609.6 mm 24 in
Tube Inner Diameter	500 µm
Tube Outer Diameter	900 µm

Material Specifications

Material Type, body	Acrylonitrile butadiene styrene (ABS)
Material Type, tubing	Thermoplastic elastomer (TPE)

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
------------------------------	--------------------------------------

Packaging and Weights

Included	Breakout unit Instruction sheet Snap together housing Twelve buffer tubes, 24 in x 900 µm
Packaging quantity	1

FPS-G2ACCFNOUT32

Regulatory Compliance/Certifications

Agency**Classification**

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

