

3-2160046-3



Fiber Optic Patch Cord, OM4, LC duplex to LC duplex, 1.8 mm LSZH, 33 m, aqua

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Middle East/Africa |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Series | 216 |

General Specifications


| | |
|-------------------------------|----------------|
| Connector A, quantity | 2 |
| Color, boot A | Beige |
| Color, connector A | Beige |
| Connector B, quantity | 2 |
| Color, boot B | Beige |
| Color, connector B | Beige |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Jacket Color | Aqua |
| Polarity | Pairs, flipped |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|-----------------------------|-------------------|
| Cord Length | 33 m 108.268 ft |
| Diameter Over Jacket | 1.8 mm 0.071 in |

Ordering Tree

3-2160046-3

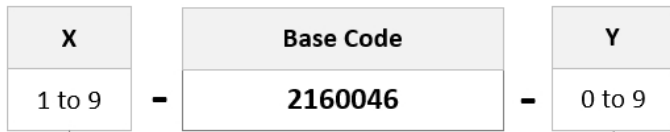

| Examples of Lengths (meters) | |
|------------------------------|-----------------|
| -5 | 5 meters |
| 1- -0 | 10 meters |
| 1- -5 | 15 meters |
| 7- -9 | 79 meters |
| 8- -y | Specific length |
| 9- -y | Specific length |

Optical Specifications

| | |
|---|-----------------|
| Fiber Mode | Multimode |
| Fiber Type | OM4, LazrSPEED® |
| Insertion Loss, maximum, connector A | 0.15 dB |
| Insertion Loss, maximum, connector B | 0.15 dB |
| Return Loss, minimum, connector A | 20 dB |
| Return Loss, minimum, connector B | 20 dB |

Environmental Specifications

| | |
|--------------------------------|---|
| Environmental Space | Low Smoke Zero Halogen (LSZH) |
| Qualification Standards | IEC 60332-1 IEC 60332-3 IEC 60754 IEC 61034 |

Packaging and Weights

| | |
|---------------------------|---|
| Packaging quantity | 1 |
|---------------------------|---|

Regulatory Compliance/Certifications

| Agency | Classification |
|------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |

3-2160046-3

| | |
|---------|--------------------|
| ROHS | Compliant/Exempted |
| UK-ROHS | Compliant/Exempted |

