


MC-HP12M-12-96-HD | With 2-7/8" antenna pipes

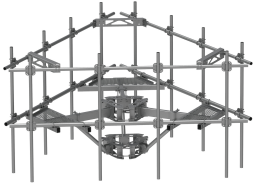

3-Sector Monopole Co-location Platform Kit, 12 in to 50 in OD, 12 ft 6 in face, includes twelve 2-7/8" x 96 in pipes

Product Classification

| | |
|----------------------|--------------------------------------|
| Portfolio | CommScope® |
| Product Type | Co-location platform |
| Ordering Note | CommScope® standard product (Global) |
| Warranty | One year |

General Specifications

| | |
|--------------------------|---------------------------------------|
| Mounting | Monopole, 304.8–1270 mm (12–50 in) OD |
| Pipe, quantity | 12 |
| Sectors, quantity | 3 |

Dimensions

| | |
|-----------------------------------|---------------------|
| Height | 2,438.4 mm 96 in |
| Face Width | 3.81 m 12.5 ft |
| Width | 3810 mm 150 in |
| Pipe Length | 2,438.4 mm 96 in |
| Mounting Diameter, maximum | 1270 mm 50 in |
| Mounting Diameter, minimum | 304.8 mm 12 in |
| Pipe Outer Diameter | 73.152 mm 2.88 in |

Material Specifications

| | |
|----------------------|--------------------------|
| Material Type | Hot dip galvanized steel |
|----------------------|--------------------------|

Mechanical Specifications

| | |
|--------------------------------|------------------------|
| Wind Rating Test Method | TIA-5053 TIA/EIA-222 |
|--------------------------------|------------------------|

MC-HP12M-12-96-HD | With 2-7/8" antenna pipes

Packaging and Weights

| | |
|---------------------------|---|
| Included | Plain end pipes (12) Platform Rail Ring mount |
| Packaging quantity | 1 |
| Weight, net | 894.938 kg 1973 lb |

* Footnotes

Warranty For more information, please consult our Product Warranty guidelines