


MP-PP15M-B

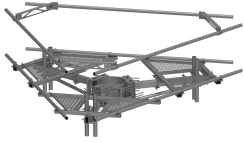

PIM Optimized Adjustable Monopole Platform Base Kit with 15ft Face - 2-7/8in OD Face Pipes & Top Rail -No Antenna Pipes Included

Product Classification

Product Type Co-location platform

General Specifications

Mounting Monopole, 304.8–1143 mm (12–45 in) OD

Pipe, quantity 0

Sectors, quantity 3

Dimensions

Face Width 4.572 m | 15 ft

Width 4,572 mm | 180 in

Face Support Pipe Diameter 73.152 mm | 2.88 in

Mounting Diameter, maximum 1,143 mm | 45 in

Mounting Diameter, minimum 304.8 mm | 12 in

Material Specifications

Material Type Hot dip galvanized steel

Mechanical Specifications

Wind Rating Test Method TIA/EIA-222

Packaging and Weights

Included Platform | Rail | Ring mount

Packaging quantity 1

Weight, net 934.718 kg | 2,060.7 lb