


# MCHD-PK14L4-12-96

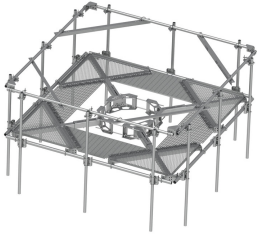

Four-sector HD Platform for 30" to 60" Monopoles, 14ft x 3.5" OD face pipes, 2.88" OD Top Rail, includes (12) 2.88" OD x 96" antenna pipes

## Product Classification

**Product Type** Monopole platform kit

## General Specifications

**Mounting** Monopole, 762–1524 mm (30–60 in) OD

**Pipe, quantity** 12

**Sectors, quantity** 4

## Dimensions

**Height** 2,438.4 mm | 96 in

**Face Width** 4.42 m | 14.5 ft

**Width** 4,419.6 mm | 174 in

**Face Support Pipe Diameter** 88.9 mm | 3.5 in

**Mounting Diameter, maximum** 1,524 mm | 60 in

**Mounting Diameter, minimum** 762 mm | 30 in

**Pipe Outer Diameter** 73.025 mm | 2.875 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Mechanical Specifications

**Wind Rating Test Method** TIA/EIA-222

## Packaging and Weights

**Included** Plain end pipes (12) | Platform | Rail | Ring mount

**Packaging quantity** 1

**Weight, net** 1,688.271 kg | 3722 lb