


UJG2XMERY

Base Product

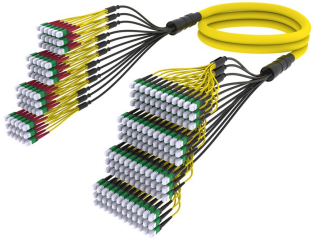

Ultra Low Loss (ULL) Singlemode MPO24 (pinned) to MPO12 (Unpinned) Pre-terminated Trunk Cable, 1728-Fiber, 12-Fiber Rollable Ribbon Central Tube, Low Smoke Zero Halogen (LSZH)/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Red
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-24/APC Male
Interface, Connector B	MPO-12/APC Female
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	1728

Dimensions

Cable Assembly Length Range (m)	30 – 999
Cable Assembly Length Range (ft)	98 – 999
Cable Assembly Length Range (km)	1.00 – 2.00

UJG2XMERY

Ordering Tree

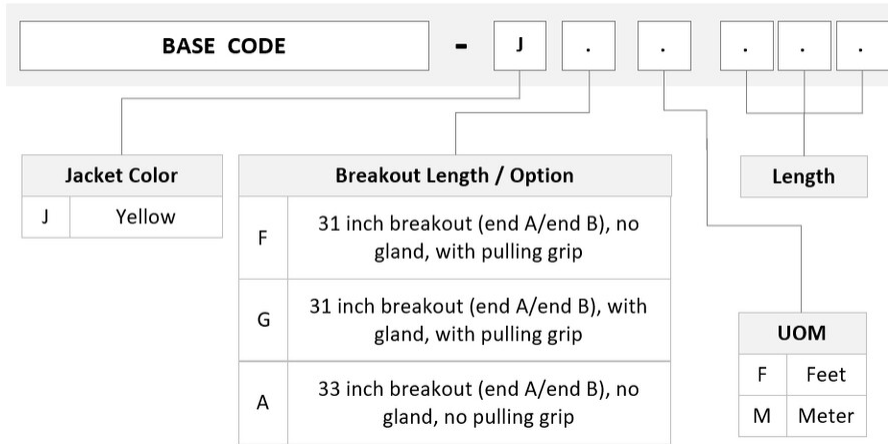

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Packaging and Weights

Packaging Type Wood reel

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

- 760244182 N-1728-LN-RR-F12YL/8G/99H/C – Fiber indoor cable, All-Dielectric, LSZH Riser-Rated, Gel-Free, Loose Tube Rollable Ribbon, 1728 fiber, Singlemode G.657.A2, Feet jacket marking, Yellow jacket color
- 860638318 – MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm
- 860651708 – TeraSPEED® MPO Female 24 Fiber Connector, green, 3.6 mm